


Terminal Boxes

ABS Range

Small ABS terminal box | SABP

IP 66,67 | IK 06/07

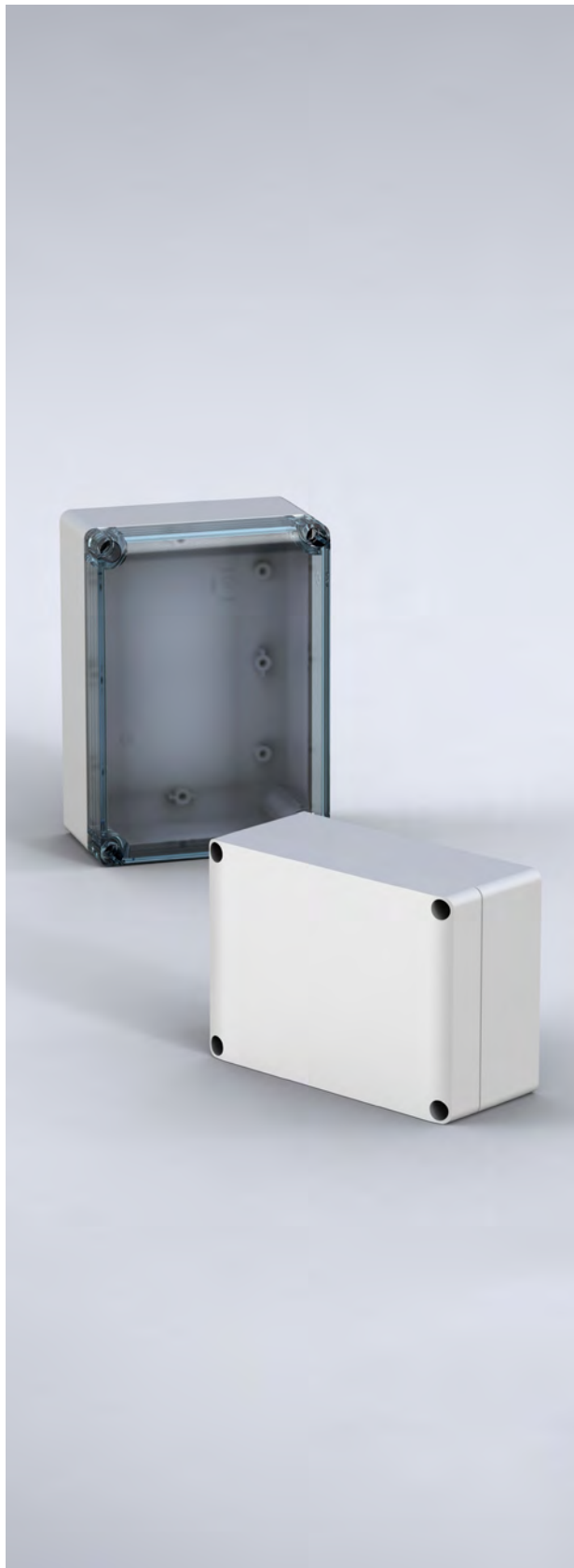

Description:

ABS box, halogen-free, suitable for indoor use. Low UV radiation resistance.

Material:

ABS.

Gasket:

Polyurethane gasket integrated in the box cover.

Temperature resistance:

-40°C to +60°C.

Flammability:

UL94 HB.

Protection:

IP 66, 67 | IK 06 (-25°C), IK 07 (+35°C).

Finish:

RAL 7035.

Approvals:

CE, GOST.

Delivery:

Body, cover, cover screws made of polyamide and mounting screws.




IP 66,67 | IK 06/07






Box dimension			Inner depth (mm)	Item no.
H	W	D		
75	125	75	60.5	SABP081308GE
75	125	100	85.5	SABP081310GE
75	125	125	110.5	SABP081313GE
125	125	75	60.5	SABP131308GE
125	125	100	85.5	SABP131310GE
125	125	125	110.5	SABP131313GE
125	175	75	60.5	SABP131808GE
125	175	100	85.5	SABP131810GE
125	175	125	110.5	SABP131813GE
125	175	150	135.5	SABP131815GE
175	175	75	60.5	SABP181808GE
175	175	100	85.5	SABP181810GE
175	175	125	110.5	SABP181813GE
175	175	150	135.5	SABP181815GE
175	250	75	60.5	SABP182508GE
175	250	100	85.5	SABP182510GE
175	250	150	135.5	SABP182515GE

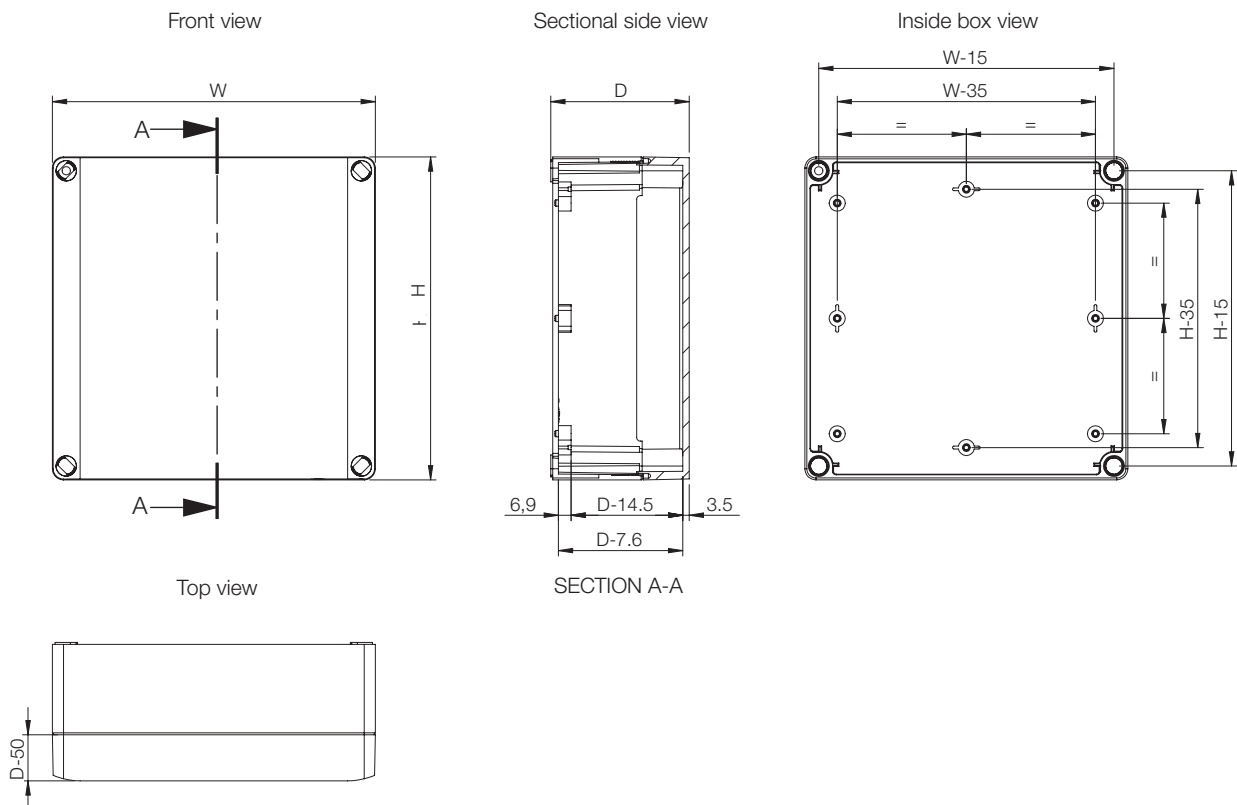Note: Terminal box with transparent cover fitted can be ordered by replacing GE with TE in the item number. Terminal box made of polycarbonate can be ordered by replacing SABP with SPCP in the item number.

Dimensional drawing | SABP

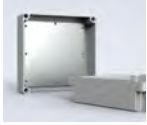

Accessories selection matrix | SABP

								
Box				Mounting		Fixing	Cover	
	H	W	D	Mounting plate	DIN rail	Wall mounting brackets	Cover plugs	Hinges
SABP081308GE	75	125	75	SMP0813E	DR350404E/DR350904E	SFL1E	SCP08E	DSHI1E
SABP081310GE	75	125	100	SMP0813E	DR350404E/DR350904E	SFL1E	SCP10E	DSHI1E
SABP081313GE	75	125	125	SMP0813E	DR350404E/DR350904E	SFL1E	SCP1315E	DSHI1E
SABP131308GE	125	125	75	SMP1313E	DR350904E	SFL1E	SCP08E	DSHI1E
SABP131310GE	125	125	100	SMP1313E	DR350904E	SFL1E	SCP10E	DSHI1E
SABP131313GE	125	125	125	SMP1313E	DR350904E	SFL1E	SCP1315E	DSHI1E
SABP131808GE	125	175	75	SMP1318E	DR350904E/DR351404E	SFL1E	SCP08E	DSHI1E
SABP131810GE	125	175	100	SMP1318E	DR350904E/DR351404E	SFL1E	SCP10E	DSHI1E
SABP131813GE	125	175	125	SMP1318E	DR350904E/DR351404E	SFL1E	SCP1315E	DSHI1E
SABP131815GE	125	175	150	SMP1318E	DR350904E/DR351404E	SFL1E	SCP1315E	DSHI1E
SABP181808GE	175	175	75	SMP1818E	DR351404E	SFL1E	SCP08E	DSHI1E
SABP181810GE	175	175	100	SMP1818E	DR351404E	SFL1E	SCP10E	DSHI1E
SABP181813GE	175	175	125	SMP1818E	DR351404E	SFL1E	SCP1315E	DSHI1E
SABP181815GE	175	175	150	SMP1818E	DR351404E	SFL1E	SCP1315E	DSHI1E
SABP182508GE	175	250	75	SMP1825E	DR351404E/DR352154E	SFL1E	SCP08E	DSHI1E
SABP182510GE	175	250	100	SMP1825E	DR351404E/DR352154E	SFL1E	SCP10E	DSHI1E
SABP182515GE	175	250	150	SMP1825E	DR351404E/DR352154E	SFL1E	SCP1315E	DSHI1E