
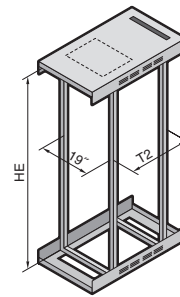


Server racks

Based on Rittal TE 7000, 1000 mm deep

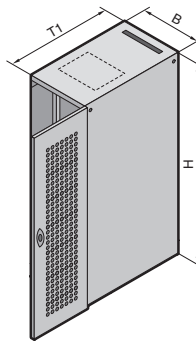

Benefits:

- No frame structure, optimum accessibility

Static load capacity:

700 kg

Material:

Sheet steel

Surface finish:

Mounting frame: Dipcoat-primed
Enclosure panels: Powder-coated, RAL 7035/9005.

Supply includes:


 
 

Self-supporting 482.6 mm (19") frame structure, vented sheet steel door front and rear, two-point locking rod, recessed handle (front) and security lock 3524 E, roof plate

with brush strip for cable entry and concealed cut-out for fan integration, levelling feet.

Detailed drawing, available on the Internet.

Server racks

5.3 B

					
U (HE)		42	42	42	42
Width (B) mm¹⁾		600	600	800	800
Height (H) mm¹⁾		2000	2000	2000	2000
Depth (T1) mm¹⁾		1000	1000	1000	1000
Distance between 482.6 mm (19") levels in its delivered state (T2) mm		745	745	745	745
Model No. TE	RAL 7035	7000.882	–	7000.892	–
as bayed enclosure without side panels, including baying kit	RAL 9005	–	7000.885	–	7000.895
Doors					
Sheet steel door front and rear, fully vented; open surface area > 67 % perforated		■	■	■	■
Roof					
Roof plate including brush strip for cable entry and with an optional fan		■	■	■	■
Base					
Base frame with maximum cut-out for cable entry or passive ventilation. Can be fitted with optional blanking panels.		■	■	■	■
Interior installation					
482.6 mm (19") mounting frames front and rear		■	■	■	■
Accessories					
Side panels, pluggable, including security lock 3524 E	7000.653	7000.663	7000.653	7000.663	
Ergoform-S handle for semi-cylinder, to exchange for the existing lock	2435.000	2452.000 ²⁾	2435.000	2452.000 ²⁾	
Fan unit, with 2 fans and thermostat, prewired ready for connection	7000.670	7000.671 ³⁾	7000.670	7000.671 ³⁾	
Transport castors, 4 castors including assembly parts	7000.672	7000.672	7000.672	7000.672	
C rail, for cable clamping in the enclosure width via cable clamps, on the 482.6 mm (19") mounting frame at the rear	7828.060	7828.060	7828.060	7828.060	
Cable clamp rail, depth-variable 500 – 895 mm, for cable attachment in the enclosure depth via cable ties	7858.162	7858.162	7858.162	7858.162	
Cable clamp rail, for cable attachment in the enclosure width via cable ties, on the 482.6 mm (19") mounting frame at the rear	7828.062	7828.062	7828.062	7828.062	
Earthing kit for TE	7000.675	7000.675	7000.675	7000.675	
TE socket strip, 8-way for earthing-pin plugs	7000.630	7000.630	7000.630	7000.630	

■ Included with the supply. ¹⁾ All sizes are nominal dimensions. For absolute dimensions, refer to detailed drawings on the Internet. ²⁾ Matt nickel-plated.