

Operating housing for desktop TFT up to 24"



System accessories Page 507 **Support arm systems** Page 135 **Stand systems** Page 164

For the installation of commercially available desktop TFTs with a screen diagonal of up to 24" in the formats 16:9/16:10.

Design:

- Viewing window with single-pane safety glass

Material:

- Enclosure and door: Sheet steel
- Handle strips: Aluminium
- Cover caps: Plastic
- Viewing window: Single-pane safety glass
- TFT holder: Sheet steel

Surface finish:

- Enclosure and door: Dipcoat primed, powder-coated on the outside, textured paint
- Handle strip: Natural anodised

Colour:

- Enclosure and door: RAL 7035
- Handle strip: Natural anodised
- Cover caps: similar to RAL 7024

Protection category IP to IEC 60 529:

- IP 55

Supply includes:

- Enclosure with cut-out and reinforcement for support arm connection Ø 130 mm
- Viewing window
- Holder for desktop TFT with VESA 75/100 locator
- Side handle strips and cover caps
- Rear door with r/h hinge
- Cam lock with 3 mm double-bit insert

Note:


- The support arm connection and door hinge may be swapped over by rotating the enclosure
- Optional: Support arm connection Ø 130 mm, preformed off-centre in the reinforcement plate, easily drilled out
- Lock insert may be exchanged for 27 mm lock inserts, type A, lock cylinder, plastic handles and T-handles, type B

Approvals:

- CSA

Technical details:

Available on the Internet

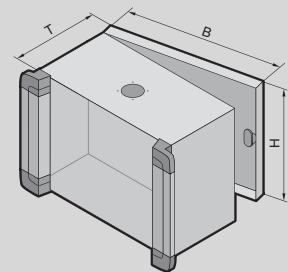

Width (B) mm	Packs of	650	Page
Height (H) mm		450	
Depth (T) mm		155	
Model No.	1 pc(s).	6321.000	
Weight kg		18.0	
Cam lock		1	
Accessories			
Lock systems		from page	560