

Switch housings



System accessories Page 507

Material:

- Enclosure: Stainless steel 1.4301 (AISI 304)
- Cover: Stainless steel 1.4301 (AISI 304), all-round foamed-in PU seal

Surface finish:

- Enclosure and cover: Brushed, grain 240

Protection category IP to IEC 60 529:

- IP 66

Protection category NEMA:


- NEMA 4X

Supply includes:

- Enclosure with cover
- Quick-release fasteners

Technical details:

Available on the Internet

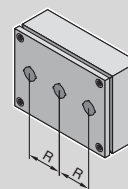

Stainless steel

	Packs of	100	160	220	280	Page
Width mm						
Height mm		100	100	100	100	
Depth mm		90	90	90	90	
Material thickness - enclosure mm		1.25	1.25	1.25	1.25	
Material thickness - cover mm		1.25	1.25	1.25	1.25	
Model No.	1 pc(s).	2384.010	2384.020	2384.030	2384.040	
Pitch pattern (R) mm		–	60	60	60	
No. of switch cut-outs Ø 22.5 mm		1	2	3	4	
Number of quick-release fasteners		2	4	4	4	

Accessories

Wall mounting bracket	4 pc(s).	1594.000	1594.000	1594.000	1594.000	587
Pressure relief stoppers	5 pc(s).	2459.500	2459.500	2459.500	2459.500	533
Cable gland HD		see page	see page	see page	see page	659
Earthing kit	5 pc(s).	2570.100	2570.100	2570.100	2570.100	646
Earth straps		see page	see page	see page	see page	644
Support rails TS 35/7.5	10 pc(s).	–	2314.000	2315.000	2315.000	614