

One-piece consoles



System accessories Page 507 Monitors, keyboards Page 706/707 Climate control Page 307 One-piece consoles, sheet steel Page 115

Material:

- Enclosure: Stainless steel 1.4301 (AISI 304), 1.5 mm
- Door or double door and console lid: Stainless steel 1.4301 (AISI 304), 2.0 mm
- Mounting plate: Sheet steel, 3.0 mm

Surface finish:

- Enclosure, door, console lid and gland plates: Brushed, grain 120
- Mounting plate: Zinc-plated

Protection category IP to IEC 60 529:

- IP 55

Protection category NEMA:

- NEMA 12

Supply includes:


- Enclosure, solid back and sides with locking rod
- Door or double door at front, with locking rod
- Console lid with lid stay and cam lock latched in the enclosure
- Locks with double-bit insert
- Gland plates, divided
- Mounting plate

Approvals:

- UL
- CSA
- TÜV
- Germanischer Lloyd
- Russian Maritime Register of Shipping
- Lloyds Register of Shipping
- VDE

Technical details:

Available on the Internet

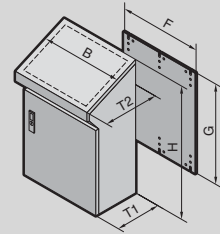

Stainless steel

Width (B) mm	Packs of	600	800	1000	1200	Page
Height (H) mm		960	960	960	960	
Depth, bottom (T1) mm		400	400	400	400	
Depth, top (T2) mm		480	480	480	480	
Mounting plate width (F) mm		530	730	930	1130	
Mounting plate height (G) mm		780	780	780	780	
Model No.	1 pc(s).	2683.600	2684.600	2685.600	2686.600	
Door(s)		1	1	2	2	
Weight kg		52.0	65.2	79.5	90.3	

Accessories						
Base/plinth, complete, 100 mm	1 pc(s).	2865.000	2869.000	2867.000	2870.000	519
Cable clamp rails	2 pc(s).	4191.000	4192.000	4336.000	4196.000	665
Support rails TS 35/15	6 pc(s).	4934.000	4935.000	4933.000	4937.000	614
Hose-proof hood		see page	see page	see page	see page	372
Lock systems		from page	from page	from page	from page	563