

E-Box EB



System accessories Page 507

Material:

- Enclosure and door: Sheet steel, all-round foamed-in PU seal

Surface finish:

- Enclosure and door: Dipcoat-primed, powder-coated on the outside, textured paint
- Mounting plate: Zinc-plated

Colour:

- RAL 7035

Protection category IP to IEC 60 529:

- IP 66

Protection category NEMA:

- NEMA 4

Supply includes:


- Enclosure with hinged door
- 180° hinge
- Cam lock with 3 mm double-bit insert
- Mounting plate

Approvals:

- UL
- CSA
- TÜV
- Germanischer Lloyd
- Russian Maritime Register of Shipping
- Lloyds Register of Shipping
- Bureau Veritas
- VDE

Technical details:

Available on the Internet

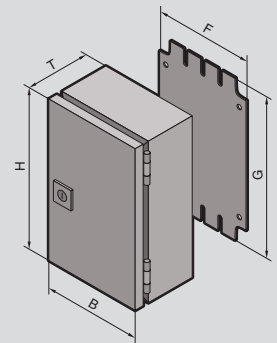

Depth 80 mm

	Packs of	150	150	200	200	200	Page
Width (B) mm		150	150	200	200	200	
Height (H) mm		150	300	200	300	400	
Depth (T) mm		80	80	80	80	80	
Mounting plate width (F) mm		125	125	175	175	175	
Mounting plate height (G) mm		135	285	185	285	385	
Material thickness - enclosure mm		1.25	1.25	1.25	1.25	1.25	
Material thickness - door mm		1.25	1.25	1.25	1.25	1.25	
Model No.	1 pc(s).	1551.500	1545.500	1546.500	1552.500	1547.500	
Weight kg		1.7	2.6	2.4	3.2	4.4	

Accessories

Wall mounting bracket	4 pc(s).	1590.000	1590.000	1590.000	1590.000	1590.000	587
Pole clamp	1 set(s)	2584.000	2584.000	2584.000	2584.000	2584.000	589
Mounting clip	30 pc(s).	2309.000	2309.000	2309.000	2309.000	2309.000	614
Support rails		see page	see page	see page	see page	see page	613
Cable glands		from page	from page	from page	from page	from page	658
Earth straps		see page	see page	see page	see page	see page	644
Lock cover	2 pc(s).	2476.000	2476.000	2476.000	2476.000	2476.000	571
Lock systems		from page	from page	from page	from page	from page	564

Depth 120 mm

Width (B) mm	Packs of	150	150	200	200	200	200	300	300	Page
Height (H) mm		150	300	200	300	400	500	300	400	
Depth (T) mm		120	120	120	120	120	120	120	120	
Mounting plate width (F) mm		125	125	175	175	175	175	275	275	
Mounting plate height (G) mm		135	285	185	285	385	485	285	385	
Material thickness - enclosure mm		1.25	1.25	1.25	1.25	1.25	1.25	1.38	1.38	
Material thickness - door mm		1.25	1.25	1.25	1.25	1.25	1.25	1.25	1.25	
Model No.	1 pc(s).	1553.500	1548.500	1549.500	1554.500	1550.500	1557.500	1555.500	1556.500	
Weight kg		2.0	3.0	2.8	3.6	5.0	6.2	5.0	6.4	
Accessories										
Wall mounting bracket	4 pc(s).	1590.000	1590.000	1590.000	1590.000	1590.000	1590.000	1590.000	1590.000	587
Pole clamp	1 set(s)	2584.000	2584.000	2584.000	2584.000	2584.000	2584.000	2584.000	2584.000	589
Mounting clip	30 pc(s).	2309.000	2309.000	2309.000	2309.000	2309.000	2309.000	2309.000	2309.000	614
Support rails		see page	see page	see page	see page	see page	see page	see page	see page	613
Cable glands		from page	from page	from page	from page	from page	from page	from page	from page	658
Earth straps		see page	see page	see page	see page	see page	see page	see page	see page	644
Lock cover	2 pc(s).	2476.000	2476.000	2476.000	2476.000	2476.000	2476.000	2476.000	2476.000	571
Lock systems		from page	from page	from page	from page	from page	from page	from page	from page	564

Depth 155 mm

Width (B) mm	Packs of	300	300	300	Page
Height (H) mm		400	600	800	
Depth (T) mm		155	155	155	
Mounting plate width (F) mm		275	275	275	
Mounting plate height (G) mm		385	585	785	
Material thickness - enclosure mm		1.38	1.38	1.38	
Material thickness - door mm		1.25	1.25	1.25	
Model No.	1 pc(s).	1577.500	1578.500	1579.500	
Weight kg		7.1	11.0	13.2	
Accessories					
Wall mounting bracket	4 pc(s).	1590.000	1590.000	1590.000	587
Pole clamp	1 set(s)	2584.000	2584.000	2584.000	589
Mounting clip	30 pc(s).	2309.000	2309.000	2309.000	614
Support rails		see page	see page	see page	613
Cable glands		from page	from page	from page	658
Earth straps		see page	see page	see page	644
Lock cover	2 pc(s).	2476.000	2476.000	2476.000	571
Lock systems		from page	from page	from page	564



Wall mounting bracket

see from page 587