

Base

Base



For enclosure depth 1000 mm

A Gland plate set	Packs of	Packs required	For enclosure width mm	
			600	800
			Model No.	
Gland plate, solid, with sliding panel, multi-piece	1 set(s)	1	5502.540	5502.550


Gland plate modules	Packs of	Packs required	For enclosure width mm	
			600	800
			Model No.	

B 1 module plate as selected			Model No.		
Gland plate, depth 250 mm	1 pc(s).	2	5001.222	5001.223	
Gland plate, depth 50 mm	1 pc(s).	1	5001.210	5001.211	
Sliding panel, depth 150 mm	1 pc(s).	1	5001.239	5001.240	
Module plate, depth 237.5 mm	Cable entry with brush strip	1 pc(s).	1	7825.361	7825.381
	Vented			7825.360	7825.380
	Cable entry with brush strip, super-airtight			7825.367	7825.387
	Cable entry, side			-	7825.388

C 2 module plates as selected			Model No.		
Gland plate, depth 250 mm	1 pc(s).	1	5001.222	5001.223	
Gland plate, depth 100 mm	1 pc(s).	1	5001.214	5001.215	
Sliding panel, depth 150 mm	1 pc(s).	1	5001.239	5001.240	
Module plate, depth 237.5 mm	Cable entry with brush strip	1 pc(s).	2	7825.361	7825.381
	Vented			7825.360	7825.380
	Cable entry with brush strip, super-airtight			7825.367	7825.387
	Cable entry, side			-	7825.388

D Cable entry, rear or front			Model No.	
Gland plate, depth 250 mm	1 pc(s).	2	5001.222	5001.223
Gland plate, depth 100 mm	1 pc(s).	1	5001.214	5001.215
Sliding panel, depth 150 mm	1 pc(s).	2	5001.239	5001.240
Foam rubber cable clamp strip	3 m	1	2573.000	2573.000

E Cable entry, centre			Model No.	
Gland plate, depth 250 mm	1 pc(s).	2	5001.222	5001.223
Gland plate, depth 100 mm	1 pc(s).	1	5001.214	5001.215
Sliding panel, depth 150 mm	1 pc(s).	2	5001.239	5001.240
Section for cable entry, centre	1 set(s)	1	8802.060	8802.080

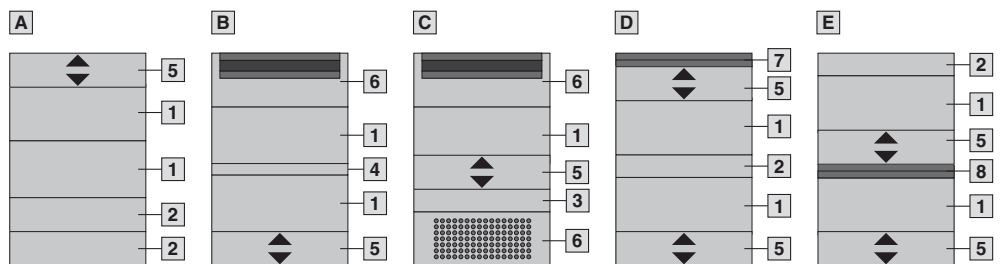

- 1 Gland plate, depth 250 mm
- 2 Gland plate, depth 150 mm
- 3 Gland plate, depth 100 mm
- 4 Gland plate, depth 50 mm
- 5 Sliding panel, depth 150 mm
- 6 Module plate, depth 237.5 mm
- 7 Self-adhesive foam cable clamp strip
- 8 Section for cable entry, centre

! Also required:

- Base mount, see page 524