

# Hygienic Design

## Accessories for system enclosure

### HD supporting structure with levelling

On request.

**Material:**


– Stainless steel tube 1.4301 (AISI 304)

**Size:**

– Height: 300 mm

**Supply includes:**

– Assembly parts

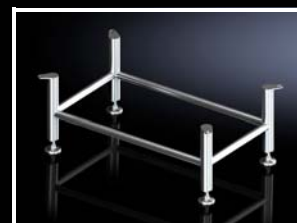

### HD side panels

Width 25 mm

For enclosures H x D mm	Packs of	Model No.
1800 x 500	1 pair(s)	<b>4000.185</b>

**Material:**

– Stainless steel 1.4301 (AISI 304), 2.0 mm

**Supply includes:**

– With assembly parts for screw-fastening from the inside



### HD baying frame

Width 44 mm

For enclosures H x D mm	Packs of	Model No.
1800 x 500	1 pc(s).	<b>4000.785</b>

**Material:**

– Stainless steel 1.4301 (AISI 304)

**Supply includes:**

– Assembly parts



### Mounting plate infill

Width 106 mm

For enclosures H mm	Packs of	Model No.
1800	1 pc(s).	<b>4000.508</b>

**Material:**

– Sheet steel, 2 mm

**Surface finish:**

– Zinc-plated

**Supply includes:**

– Assembly parts



### HD angled roof 30°

open at the sides

W x D mm	Packs of	Model No.
400 x 500	1 pc(s).	<b>4000.545<sup>1)</sup></b>
600 x 500	1 pc(s).	<b>4000.565</b>
800 x 500	1 pc(s).	<b>4000.585</b>
1200 x 500	1 pc(s).	<b>4000.525<sup>1)</sup></b>

**Material:**

– Stainless steel 1.4301 (AISI 304)

**Supply includes:**

– Assembly parts

<sup>1)</sup> Extended delivery times.



### HD side panels for angled roof

D mm	Packs of	Model No.
500	1 pair(s)	<b>4000.505</b>

**Material:**

– Stainless steel 1.4301 (AISI 304)

**Supply includes:**

– Assembly parts

